
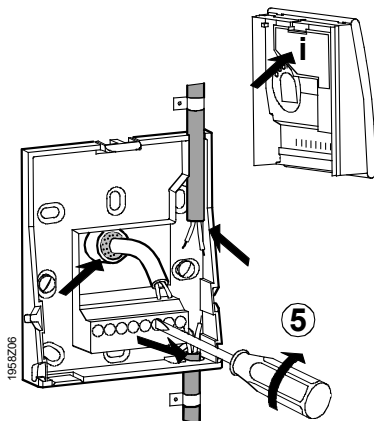
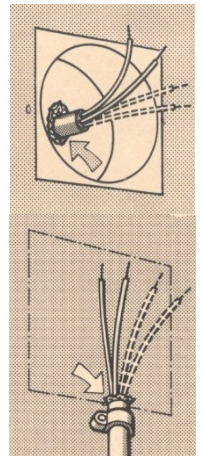
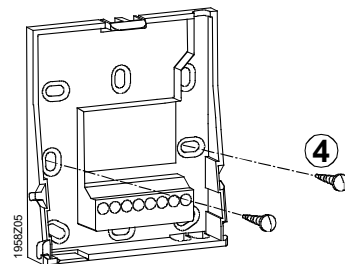
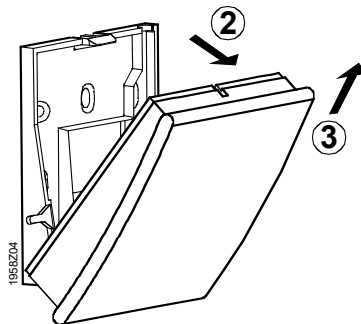
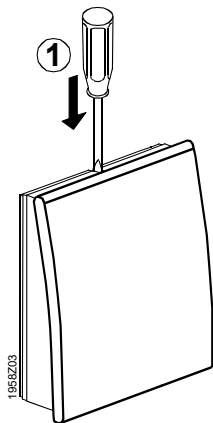



- de** Montageanleitung
- en** Mounting instructions
- fr** Instructions de montage
- sv** Monteringsinstruktion
- nl** Montage-aanwijzing
- it** Istruzioni di montaggio
- fi** Asennusohje
- es** Instrucciones de montaje
- da** Monteringsvejledning
- tr** Montaj talimatları

QPA10.. QPA20..

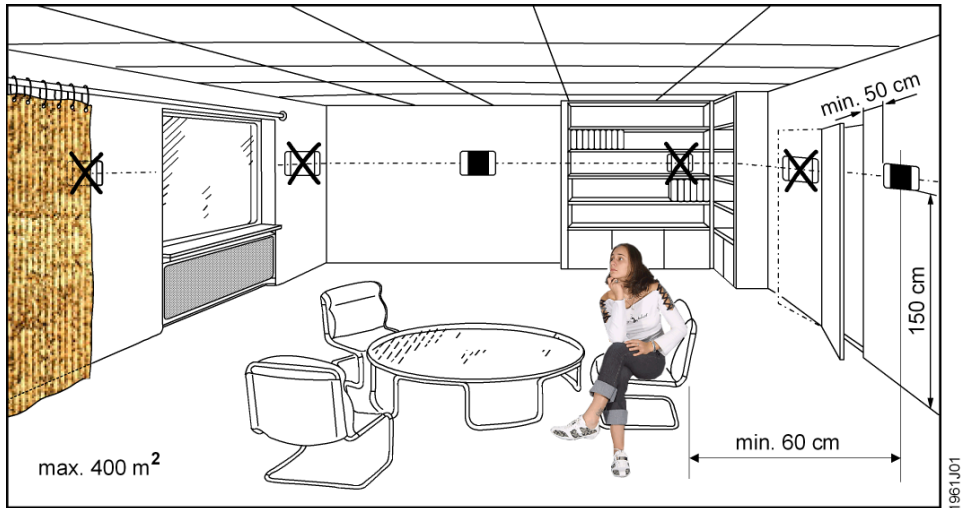


	min.	max.
	0.25 mm ²	1 x 1.5 mm ²
	0.25 mm ²	2 x 1.5 mm ²
	⚠	


1958T01

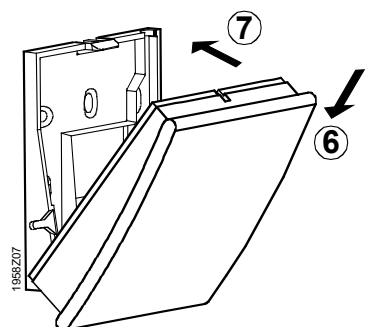


QPA1000

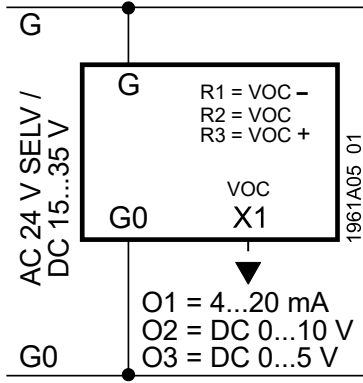


QPA2000

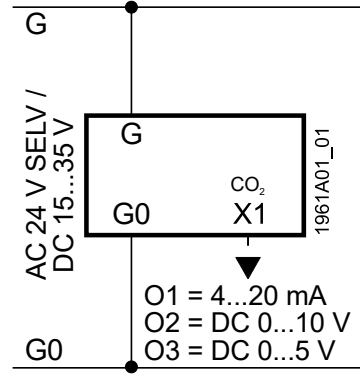


QPA2002, QPA2002D

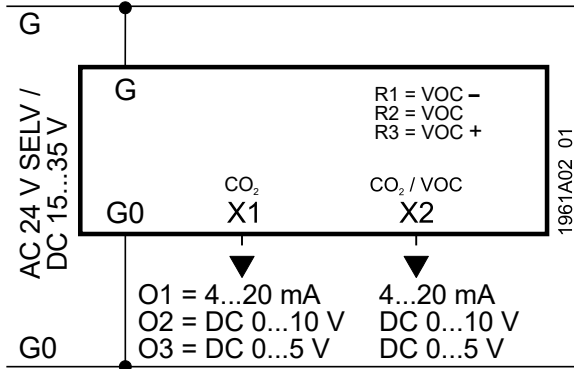



QPA2060, QPA2060D

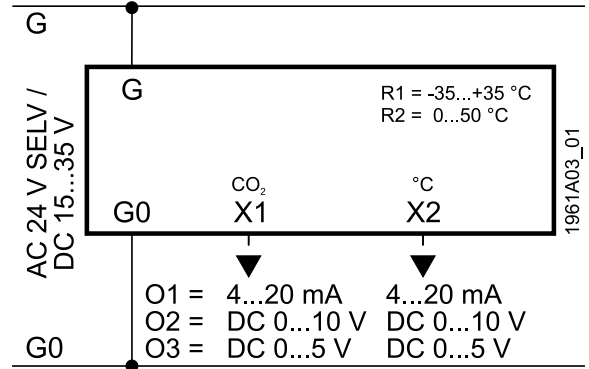

QPA2062, QPA2062D

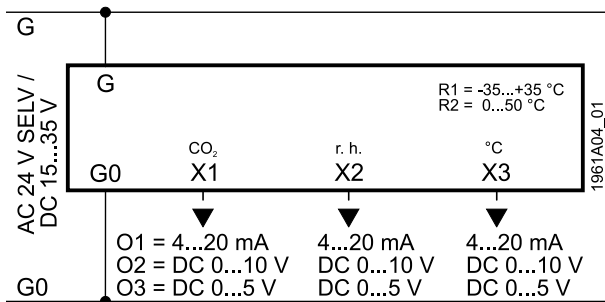

QPA2080, QPA2080D

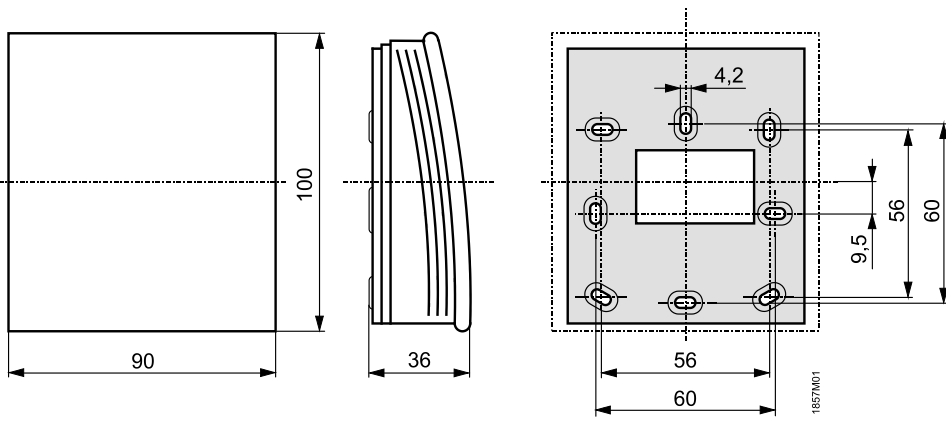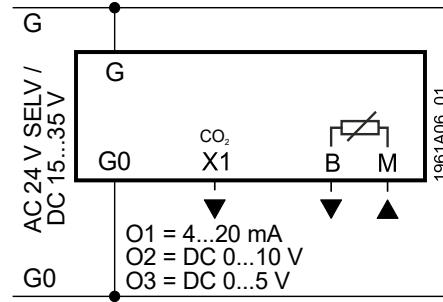

Masse in mm
 Dimensions in mm
 Dimensions en mm
 Mått i mm
 Afmetingen in mm
 Dimensioni in mm
 Mitat mm
 Dimensiones en mm
 Mål i mm
 Boyutlar mm